

Purchase a METTLER TOLEDO Balance And Receive FISHER SCIENTIFIC BUCK\$

METTLER TOLEDO and Fisher Scientific team up to offer you FISHER SCIENTIFIC BUCK\$. Purchase a METTLER TOLEDO balance or titrator through Fisher Scientific and receive free FISHER SCIENTIFIC BUCK\$ to use on your choice of any product(s) from Fisher Scientific. Visit www.fishersci.com for a complete listing of products.




\$400 in FISHER SCIENTIFIC BUCK\$

Excellence Plus Balances (XP)
Entry Level Titrators (DL15/DL22/DL28)

\$300 in FISHER SCIENTIFIC BUCK\$

Excellence Balances (XS)

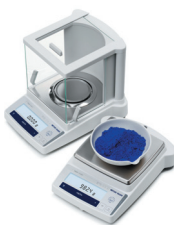

\$200 in FISHER SCIENTIFIC BUCK\$

Classic Plus (AB/PB-S/FACT)

1. Include Fisher Scientific Invoice and fax to: (800) 866-9840

METTLER TOLEDO New Product Information

Model Purchased
S/N
Purchase Date

2. Cash in your FISHER SCIENTIFIC BUCKS! Choose any product(s) from Fisher Scientific and enter information below. A Fisher Scientific representative will contact you for payment on any product requests beyond your FISHER SCIENTIFIC BUCKS allocation.*

Qty	Part #	Description	Price
TOTAL			

* Must be an existing part number not beginning in NC. Redemption values are at list price.

3. Send my Fisher Scientific products to:

Contact Name		Company
Address		Bldg/Room
City	State	Zip
Phone	Fax	Email

Only customers in U.S. are eligible. Void where prohibited by law or company policy. Not valid with other offers/promotions. Customer must attach completed form along with copy of their invoice. Offer valid for a limited time. One time opportunity for redemption (no balance of FISHER SCIENTIFIC BUCKS may be carried). Redemption forms must be received no later than 30 days after purchase. Please allow 4-6 weeks to receive your additional Fisher Scientific product(s).

METTLER TOLEDO



Mettler Toledo Ca\$h In For Buck\$

Earn \$400 in Fisher Scientific Bucks with the products listed below

Fisher Catalog	Model Number	Description
01910728	DL32D	Coulometric Karl Fischer Titrator, with diaphragm
01910727	DL32X	Coulometric Karl Fischer Titrator, without diaphragm
01911350	XP105DR	Excellence Plus XP Analytical Balance, 0 to 31/0 to 120g, 0.01/0.1mg readability
01910700	DL15	Potentiometric Titrator for Endpoint Titrations
01910701	DL22	Potentiometric Titrator for Food and Beverage Titrations
01910702	DL28	Potentiometric Titrator for Food, Water and Chemical Titrations
01910726	DL31	Volumetric Karl Fischer Titrator
01911351	XP205	XP Analytical Balance, 0 to 220g, 0.01mg readability
01911353	XP204	XP Analytical Balance, 0 to 220g, 0.1mg readability
01911354	XP504	XP Analytical Balance, 0 to 520g, 0.1mg readability
01911352	XP205DR	XP Analytical Balance, 0 to 81/0 to 220g, 0.01/0.1mg readability
01911355	XP504DR	XP Analytical Balance, 0 to 101/0 to 520g, 0.1/1mg readability
01910655	XP802S	XP Balance S-Platform, 0 to 810g, 0.01g readability
01910422	XP5003SDR	XP Balance, 0 to 1000/0 to 5100g, 1mg/10mg readability
01910361	XP10001S	XP Balance, 0 to 10100g, 0.1g readability
01910367	XP10002S	XP Balance, 0 to 10100g, 10mg readability
01910371	XP603SDR	XP Balance, 0 to 120/0 to 610g, 1mg/.01g readability
01910365	XP6002SDR	XP Balance, 0 to 1200/0 to 6100g, .01/.1g readability
01910362	XP1202S	XP Balance, 0 to 1210g, .01g readability
01910372	XP1203S	XP Balance, 0 to 1210g, 1mg readability
01910368	XP10002SDR	XP Balance, 0 to 2000/0 to 10100g, 10mg/100mg readability
01910369	XP203S	XP Balance, 0 to 210g, 1mg readability
01910363	XP4002S	XP Balance, 0 to 4100g, .01g readability
01910358	XP4001S	XP Balance, 0 to 4100g, .1g readability
01910421	XP2003SDR	XP Balance, 0 to 500/0 to 2100g, 1mg/10mg readability
01910364	XP6002S	XP Balance, 0 to 6100g, .01g readability
01910359	XP6001S	XP Balance, 0 to 6100g, 0.1G
01910370	XP603S	XP Balance, 0 to 610g, 1mg readability
01910366	XP8002S	XP Balance, 0 to 8100g, .01g readability
01910360	XP8001S	XP Balance, 0 to 8100g, 0.1g readability
01910423	XP6002MDR	XP Electronic Toploading Balance, 0 to 1200/0 to 6100g, 10mg/100mg readability
01910427	XP12001M	XP Electronic Toploading Balance, 0 to 12100g, 100mg readability
01910418	XP204S	XP Electronic Toploading Balance, 0 to 210g, 0.1mg readability
01910420	XP404SDR	XP Electronic Toploading Balance, 0 to 210g, 0.1mg readability
01910424	XP12002MDR	XP Electronic Toploading Balance, 0 to 2400/0 to 12100g, 10mg/100mg readability
01910419	XP404S	XP Electronic Toploading Balance, 0 to 410g, 0.1mg readability
01910426	XP8001MDR	XP Electronic Toploading Balances, 0 to 1800/0 to 8100g, 100mg/1000mg readability
01910425	XP8001M	XP Electronic Toploading Balances, 0 to 8100g, 100mg readability
01910651	XP56DR	XP Microbalance, 0 to 11/0 to 52g, 2ug/0.01mg readability
01910671	XP26DR	XP Microbalance, 0 to 22g, .01mg readability
01910670	XP26	XP Microbalance, 0 to 22g, 0.001mg readability
01910650	XP56	XP Microbalance, 0 to 52g, 0.001g readability
01910015	XP6	XP Microbalance, 0 to 6.1g, 1ug readability
01910451	XP16001L	XP Precision Balance L-Platform, 0 to 16100g, 0.1g readability
01910455	XP16000L	XP Precision Balance L-Platform, 0 to 16100g, 1g readability
01910452	XP32001L	XP Precision Balance L-Platform, 0 to 32100g, 0.1g readability
01910456	XP32000L	XP Precision Balance L-Platform, 0 to 32100g, 1g readability
01910453	XP32001LDR	XP Precision Balance L-Platform, 0 to 6100/0 to 32100g, 0.1/1g readability
01910454	XP64001L	XP Precision Balance L-Platform, 0 to 64100g, 0.1g readability
01910457	XP64000L	XP Precision Balance L-Platform, 0 to 64100g, 1g readability
01910450	XP8001L	XP Precision Balance L-Platform, 0 to 8100g, 0.1g readability
01910464	XP16001M	XP Precision Balance M-Platform, 0 to 16100g, 0.1g readability
01910659	XP16001MDR	XP Precision Balance M-Platform, 0 to 16100g, 1g readability
01910465	XP20001M	XP Precision Balance M-Platform, 0 to 20100g, 0.1g readability
01910466	XP20000M	XP Precision Balance M-Platform, 0 to 20100g, 1g readability
01910656	XP2002S	XP Precision Balance S-Platform, 0 to 2100g, 0.01g readability
01910658	XP2001S	XP Precision Balance S-Platform, 0 to 2100g, 0.1g readability
01910657	XP4002SDR	XP Precision Balance S-Platform, 0 to 800/0 to 4100g, .01/.1g readability
01910014	XP2U	XP Ultramicro Balance, 0 to 2.1g, 0.1ug repeatability

Earn \$300 in Fisher Scientific Bucks with the products listed below

Fisher Catalog	Model Number	Description
01910325	XS205DU	XS Analytical Balance, 0 to 220/0 to 81g, 0.1mg/0.01mg readability
01910323	XS204DR	XS Analytical Balance, 0 to 220/0 to 81g, 1mg/0.1mg readability
01910324	XS204	XS Analytical Balance, 0 to 220g, 0.1mg readability
01910322	XS105DU	XS Analytical Balance, 0 to 41/120g, 0.1mg/0.01mg readability
01910320	XS64	XS Analytical Balance, 0 to 61g, 0.1mg readability
01910416	XS10001M	XS Balance, 0 to 10100g, 0.1g resolution
01910417	XS10000M	XS Balance, 0 to 10100g, 1g resolution
01910404	XS1003S	XS Balance, 0 to 1010g, 1mg readability
01910415	XS6001MDR	XS Balance, 0 to 1200/0 to 6100g
01910410	XS6002SDR	XS Balance, 0 to 1200/0 to 6100g, 0.01/0.1g readability
01910321	XS104	XS Balance, 0 to 120g, 0.1mg readability
01910403	XS603SDR	XS Balance, 0 to 120g/0 to 610g, Repeatability: 1mg/5mg
01910406	XS2002S	XS Balance, 0 to 2100g, 0.01g readability
01910400	XS203S	XS Balance, 0 to 210g, 0.1g readability
01910411	XS4001S	XS Balance, 0 to 4100g, 0.1g readability
01910407	XS4002S	XS Balance, 0 to 4100g, 0.1g readability
01910401	XS403S	XS Balance, 0 to 410g, 1mg readability
01910412	XS6001S	XS Balance, 0 to 6100g, 0.1g resolution
01910409	XS6002S	XS Balance, 0 to 6100g, 0.01g readability
01910414	XS6001M	XS Balance, 0 to 6100g, 0.1g resolution
01910402	XS603S	XS Balance, 0 to 610g
01910408	XS4002SDR	XS Balance, 0 to 800/0 to 4100g, 0.01/0.1g readability
01910413	XS8001S	XS Balance, 0 to 8100g
01910405	XS802S	XS Balance, 0 to 810g
01910016	XS3DU	XS Microbalance, 0 to 3g/0 to 800mg, 10ug/1ug readability
01910459	XS16001L	XS Precision Balance L-Platform, 0 to 16100g, 0.1g readability
01910462	XS16000L	XS Precision Balance L-Platform, 0 to 16100g, 1g readability
01910460	XS32001L	XS Precision Balance L-Platform, 0 to 32100g, 0.1g readability
01910463	XS32000L	XS Precision Balance L-Platform, 0 to 32100g, 1g readability
01910461	XS32001LDR	XS Precision Balance L-Platform, 0 to 6400/0 to 32100g, 0.1g/1g readability
01910458	XS8001L	XS Precision Balance L-Platform, 0 to 8100g, 0.1g readability
01910467	XS16001M	XS Precision Balance M-Platform, 0 to 16100g, 0.1g readability
01910660	XS12001MDR	XS Precision Balance M-Platform, 0 to 2400/0 to 12100g, 0.1/1g readability

Earn \$200 in Fisher Scientific Bucks with the products listed below

Fisher Catalog	Model Number	Description
01916253	AB104-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 110g, 0.1mg readability
01916254	AB204-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 220g, 0.1mg readability
01916250	AB135-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 31/0 to 120g, 0.03/0.1mg readability
01916255	AB304-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 320g, 0.1mg readability
01916252	AB54-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 51g, 0.1mg readability
01916251	AB265-S/FACT	AB-S/FACT Classic Plus Analytical Balance, 0 to 61/0 to 220g, 0.03/0.1mg readability
01916264	PB3002-SDR/FACT	BALANCE 0 to 600/0 to 3100g, 0.1/0.01g readability
0191868	PB8000 A	Balance, Certified, 0 to 8100g, 1g readability
01941	PB1501-S/A	Basic Balance, 0 to 1510g, 0.1g readability
01938	PB1502-S/A	Basic Balance, 0 to 1510g, 10mg readability
01934	PB153-S/A	Basic Balance, 0 to 151g, 1mg readability
01939	PB3002-S/A	Basic Balance, 0 to 3000g, 10mg readability
01942	PB3001-S/A	Basic Balance, 0 to 3100g, 0.1g readability
01943	PB5001-S/A	Basic Balance, 0 to 5100g, 0.1g readability
01940	PB3002-SDR/A	Basic Balance, 0 to 600g, 10mg readability
01936	PB303-SDR/A	Basic Balance, 0 to 60g, 1mg readability
01916259	PB403-S/FACT	Classic Plus PB-S/FACT Balance, 0 to 410g, 0.001g readability
01916258	PB303-SDR/FACT	Classic Plus PB-S/FACT Balance, 0 to 60/0 to 310g, 0.01g/0.001g readability
01916261	PB602-S/FACT	Classic Plus PB-S/FACT Balance, 0 to 610g, 0.01g readability
093198	PB403-S/21	PB403-S/21 BAL TALLSHIELD
01916260	PB503-S/FACT	PB503-S/FACT Balance, 0 to 510g, 0.001g readability
01916270	PB8000-S/FACT	PB8000-S/FACT Balance, 0 to 8100g
01916269	PB8001-S/FACT	PB-S/FACT Balance, 0 to 8100g, 0.1g readability
01916262	PB1502-S/FACT	PB-S/FACT Balance, 0 to 1510g, 0.01g readability
01916266	PB1501-S/FACT	PB-S/FACT Balance, 0 to 1510g, 0.1g readability
01916256	PB153-S/FACT	PB-S/FACT Balance, 0 to 151g, 0.001mg readability
01916263	PB3002-S/FACT	PB-S/FACT Balance, 0 to 3100g, 0.01g readability
01916267	PB3001-S/FACT	PB-S/FACT Balance, 0 to 3100g, 0.1g readability
01916265	PB4002-S/FACT	PB-S/FACT Balance, 0 to 4100g, 0.01g readability
01916268	PB5001-S/FACT	PB-S/FACT Balance, 0 to 5100g, 0.1g readability
01916257	PB303-S/FACT	PB-S/FACT Series Balances, 0 to 310g, 0.001g readability