

**METH LAB INTERDICTION TEAMS**  
**FISHER SAFETY CAN MAKE SURE YOU'RE READY FOR THE CHALLENGE**

**MAKE FISHER SAFETY  
YOUR ALLY  
IN THE WAR ON DRUGS**

Fisher Safety understands the hazards that first responders face at meth lab sites and the necessary equipment required to keep them safe on the job.

- ♦ **Strategic relationships with leading first responder product manufacturers** allow us to serve you as your single source for thousands of quality safety products
- ♦ **Comprehensive clandestine lab training series** addresses the various needs of drug interdiction teams and other emergency responders—from basic awareness through advanced (technician) level courses
- ♦ **24/7 customer service and e-commerce capabilities** with a national distribution network ensure our ability to get the products you need when you need them
- ♦ **Skilled sales representatives** provide individualized service to ensure that your requirements are met with total satisfaction

This brochure features many key products that interdiction teams use to “detect and protect” in meth lab responses. For a total product resource, bookmark our Web site, [www.fishersafety.com](http://www.fishersafety.com) to see a full line of products specific to drug task forces and interdiction teams. Should you require immediate assistance with your product selection, or have questions, call your Fisher Safety Customer Service Representative at **1-800-772-6733**.

## DETECTION



### Dräger™ Multi-IMS Chemical Agent Detector

Lightweight detector uses sensor technology based on Open Loop Ion Mobility Spectrometry (IMS) to quickly detect toxic industrial chemicals (TICs) and chemical warfare agents (CWAs), even in low concentrations. Suitable for use as a personal measuring device or as a surveying monitor.

**Cat. No. 19-130-0727**



### Dräger™ Clan Lab Simultest Set

Five-tube set for simultaneous detection of common gases associated with production methods of methamphetamine—ammonia, hydrochloric acid, iodine, phosgene, and phosphine. Pump and manifold are sold separately.

**Cat. No. 19-080-708**

### Dräger™ accuro™ Bellows Pump

Ergonomic design allows easy direct, onsite measurement of more than 350 gases, vapors, and aerosols.

**Cat. No. 17-986-70A**

### Simultest Adapter

Includes 1m extension hose, quick connection and set opener

**Cat. No. 19-080-703**



### MSA® Sirius™ Multigas Detector

Integrates high-performance photoionization detector sensor with a multigas detector for up to four gases. Users are able to simultaneously monitor for volatile organic compounds (VOCs) with low vapor pressures while measuring for combustible, toxic, and oxygen-deficient atmospheres.

**Cat. No. 19-123-398**

(LEL, O<sub>2</sub>, CO, H<sub>2</sub>S with rubber boot and Cordura® jacket)

**Cat. No. 19-123-399**

(LEL, O<sub>2</sub>, H<sub>2</sub>S with rubber boot and Cordura® jacket)

**Cat. No. 19-123-400**

(LEL, O<sub>2</sub>, CO with rubber boot and Cordura® jacket)

**Cat. No. 19-123-401**

(LEL, O<sub>2</sub>, CO, H<sub>2</sub>S with rubber boot, Cordura® jacket, and datalogging)

## PPE/APPAREL



### Onguard® Hazmax® Boots

Steel-toe, over-the-sock knee boots feature full steel midsoles and steel ladder shanks, molded Footbed® insoles, kick-off lugs, chemical-resistant uppers, and yellow Ultragrip® outsoles.

**Cat. Nos. 17-985-403B through L**  
(Sizes 6 through 15)

## PPE/GLOVES



### North™ Butyl Gloves

Butyl synthetic rubber gloves, with highest permeation resistance to gas or water vapors. Curved fingers and hand design for greater comfort. Rolled cuffs. 14" long. 17mil thick. Sold by the pair.


**Cat. Nos. 11-394-8A through D**  
(Sizes 8-11)



### Best® N-DEX® NightHawk™ Gloves

Designed for applications requiring protection and dexterity, this chemical-resistant nitrile glove is perfect for workers in law enforcement and security applications. Textured fingertips for exceptional tactility. Excellent ESD properties. Length, 9½" (24cm). Thickness, 4mil. Black. Pack of 50.

**Cat. Nos. 19-130-1300B through E**  
(Sizes S-XL)

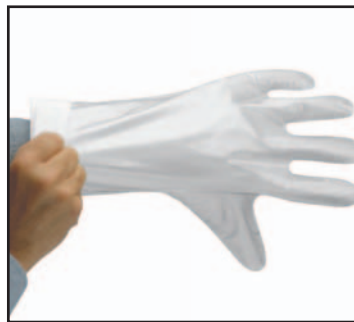

### Ansell® Barrier™ Gloves

Patented electronic seam fusion technology securely seals protective film and liner together to help absorb and dissipate perspiration for a cooler, more comfortable fit. Made from an exceptionally thin 2.5mil chemical-resistant, five-layer film that can be worn as a liner under heavier nitrile, neoprene, or PVC gloves. Provide exceptional flexibility and tactility.

**Cat. No. 19-034-564A through F**  
(Sizes 6-11)

## PPE/RESPIRATORY



### MSA® Millennium® CBRN Gas Mask

CBRN-approved gas mask accommodates a military-style, 40mm threaded canister. Dual-canister mounts permit weapon sighting from either shoulder. Overall size is compatible with most visored police helmets. Provided with drinking tube that can be used for replenishing fluids in potentially contaminated environments.

**Cat. Nos. 19-130-0458 through 19-130-0460**  
(Masks, S-L)

**Cat. No. 19-130-0457**  
(CBRN canister)

**Cat. No. 19-003-369**  
(Optional ESP II voice amplifier)





**DuPont™ Low-Visibility Tychem ThermoPro® Coveralls**

Combine the chemical protection of Tychem® and thermal protection of Nomex® into a single-layer garment. Designed to provide Hazmat responders with permeation protection against a broad range of toxic industrial chemicals and chemical warfare agents and to increase escape time from flash fires. Case of 2.

**Cat. Nos. 19-130-4873 through 19-130-4878**  
(S-XXL, with hemmed ankles)

**Cat. Nos. 19-130-4879 through 19-130-4884**  
(S-XXL, with attached sock boots)



**Kappler™ Chem-Tape®**

Seals gaps in protective apparel at sleeve, ankle, hood and storm flap. Provides a durable reinforcement, but tears easily for quick application. Roll measures 2" x 60 yd. (5cm x 55m).

**Cat. No. 19-036-34**



**DuPont™ Cool-Guard® Personal Cooling Vest**

Vest provides cooling without the discomfort, vasoconstriction, or moisture buildup of typical icepack systems. Phase-change gel packs absorb heat generated by the body; provide 1½ to 2 hours of cooling at 110°F.

**Cat. No. 19-088-787**  
(Vest and 4 gel packs)

**Cat. No. 19-034-984G**  
(Vest only)

**Cat. No. 19-034-984J**  
(Replacement gel packs)

**THERMAL IMAGERS**



**Bullard® Tacsight™ Thermal Imager**

Optics and detection components are engineered specifically for law enforcement applications. Detects extremely small differences in temperature, enabling officers to see heat signatures and distinguish people, even with dark or camouflage clothing, from their immediate surroundings without light.

**Cat. No. 19-130-0491**  
(Imager)

**Cat. No. 19-130-0492**  
(Imager with video recorder)

PHONE: 1-800-772-6733

FAX: 1-800-772-7702

ONLINE: [fishersafety.com](http://fishersafety.com)



**MSA® BlackHawk™ Tactical SCBA**

SCBA design eliminates reflections or sounds that might compromise concealment. For use in tactical situations. Heads-Up Display's LED array serves as a low pressure warning device and cylinder pressure gauge, eliminating the need for an audible whistle. Black cylinder shroud encompasses both cylinder and air mask components.

**Cat. No. 19-121-639**  
(4500psi, 60 min. duration, with Speed-On® head harness)

**Cat. No. 19-121-647**  
(4500psi, 60 min. duration, with rubber head harness)



**Scott® Swat-Pak™ FR SCBA**

Unique all-black design designed exclusively for use by law enforcement personnel in stealth situations involving unknown chemical or biological hazards. Silent advantage—does not include many "standard" SCBA components such as flashing, ringing, or whistling alarms; reflective labeling or fabric; and shiny hardware, which could pose a hazard in high-risk scenarios. Complete Assembly includes: Black Kevlar™ harness, AV-2000™ facepiece with Kevlar™ head harness, Quick-Connect E-Z Flo™ Plus CBRN regulator, Heads-Up Display, Rapid Intervention Crew/Universal Airline Connection, and soft carrying case.

**Cat. No. 19-120-3893**



**MSA® Advantage® 3200 Twin-Port Respirators**

Compatible with existing NIOSH-approved Advantage series cartridges and filters, the twin-port 3200 respirator features lower breathing resistance than traditional full-facepiece respirators, increasing airflow and enhancing worker productivity. Soft, pliable 3000 series silicone facemask and rubber head harness don quickly; pre-adjustable straps ensure a consistent fit and tighter seal. Wraparound facepiece lens provides a wide, distortion-free field of vision protected by a scratch-resistant lens coating and a fog-reducing standard nosecup.

**Cat. No. 19-041-906A through C**

**Organic Vapor/P100 Cartridge**

Lightweight for comfort but designed for maximum protection. Bayonet-style mounting allows easy installation—cartridges lock into place with a single twist. Two cartridges per pack.

**Cat. No. 19-003-230**



## LIGHTS



### Streamlight® Stinger® XT HP Flashlight


Lightweight, compact, and powerful rechargeable flashlight for tactical operations. Tailcap switch allows tactical use of the blinding beam. Continuous run time of one hour. NiCd battery can be recharged up to 1,000 times. Weight: 14.6 oz.; Length: 8<sup>5</sup>/<sub>8</sub>". Black.

**Cat. No. 19-500-489**  
(Flashlight only)

**Cat. No. 19-500-490**  
(Flashlight with Steady Charge charger)

**Cat. No. 19-500-491**  
(Flashlight with Fast Charge charger)

**Cat. No. 19-500-493**  
(Flashlight with Steady Charge and piggyback holder)

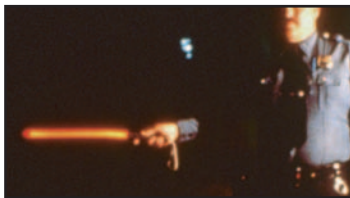

### OmniGlow® Lightsticks

Provide visible and infrared light up to one mile. Snaplight® lightstick is a hexagonal tube with an eyelet and hook. Length, 6" (15.2cm). SafetyGlow™ lightstick includes wire bipod to hold lightstick in upright position. Length, 10" (25.4cm).

**Cat. No. 19-006-103**  
(Snaplight®, Red, 30 min. duration)

**Cat. No. 19-006-110**  
(Snaplight®, Orange, 12 hr. duration)

**Cat. No. 19-006-107**  
(SafetyGlow™, Yellow, 2 hr. duration)

## CLANDESTINE LABORATORY TRAINING SERIES

### METHAMPHETAMINE AWARENESS COURSE

**Length: 8 hours • Student/Instructor Ratio: 7:1 • Class Size: Unlimited**

Designed to heighten awareness and understanding of the basic building blocks of methamphetamine production. Discusses chemicals typically used to manufacture methamphetamine and ways to protect personnel from this plague. All instructors are actively involved in methamphetamine laboratory investigations with their agencies.

### CLAN LAB FIRST RESPONDER

**Length: 8 hours • Student/Instructor Ratio: 7:1 • Class Size: Unlimited**

Familiarizes individuals with the hazards and initial response actions that should be taken upon discovery of a clandestine laboratory operation. Introduces participants to basic drug classification and common drug lab methods (emphasis on methamphetamine labs), indicators of drug lab operations, common laboratory equipment and chemical substitutions, first-on-scene safety and response procedures, environmental and public safety and intelligence updates. Designed for personnel who might chance upon a clandestine drug lab operation such as patrol officers, drug task forces, firefighters, hazmat personnel, code enforcement, and others.

### CLAN LAB OPERATIONS COURSE

**Length: 16 hours • Student/Instructor Ratio: 7:1 • Class Size: 28**

Covers both the popular Nazi and Red Phosphorus manufacturing methods of methamphetamine. Designed to instruct personnel in what to look for and how to keep safe from possible exposure and contamination. Learn to recognize the equipment, chemicals and precursors that are used to manufacture methamphetamine. Open to all law enforcement, military, fire department and criminal justice professionals involved in the apprehension and prosecution of criminals.

### ADVANCED CLAN LAB INVESTIGATION AND PROCESSING (TECHNICIAN)

**Length: 5 days • Student/Instructor Ratio: 6:1 • Class Size: 24**

Designed to take participants to the next level of investigating clandestine methamphetamine laboratories, this intense course is packed with great hands-on learning that allows participants to put principle into practice. Participants will learn what to do upon arrival at the scene of a clandestine methamphetamine laboratory, the duties and responsibilities of a hot-zone case officer, how to enter a scene and take proper fingerprints, how to sample chemicals from both Nazi and Red Phosphorus labs, and other key investigation principles.

*\* Fisher Safety provides customized training and consulting services to its customers through alliances with third-party service providers. Any relationship between a Fisher customer and an alliance consultant arising out of a referral by Fisher shall be according to the terms of any agreement entered into independently by the consultant and customer.*

**FOR MORE INFORMATION ON THESE AND OTHER TRAINING/CONSULTING SERVICES AVAILABLE THROUGH FISHER SAFETY PLEASE CONTACT:**

**OR:**

**Steve Grego, Manager - Training and Consulting Services at 412-490-8850**

## PERSONAL DECONTAMINATION AND COLLECTION



### DuPont™ Tychem® Responder® Portable Decon Shower

Chemical-resistant Responder® fabric basin and snaplocking PVC framework assemble in about 5 minutes. Shower kit includes catch basin, PVC pad, adjustable wand with stand, and carrying bag. Removable spray wand can be positioned overhead for stationary use. Optional curtain and framework kit includes four-wall Responder® fabric curtain, PVC framework, and carrying case.

**Cat. No. 18-999-2579A**  
(Shower kit)

**Cat. No. 18-999-2579B**  
(Curtain with framework kit)

**Cat. No. 19-812-743**  
(Replacement catch basin)

**Cat. No. 19-822-362**  
(Carrying case)



### Eagle® Overpack Drums

Can be used with all packing groups—I, II, III—of hazardous materials. Made of high-density polyethylene with UV inhibitors for superior strength and chemical resistance.

**Cat. No. 19-999-348**  
(65 gal.)

**Cat. No. 19-999-349**  
(95 gal.)



**For customer service, call 1-800-772-6733.**

**To fax an order, use 1-800-772-7702.**

**To order online: [www.fishersafety.com](http://www.fishersafety.com)**

©2005 Fisher Scientific  
Litho in U.S.A.

05-6860  
BM/ES 5M-PENT-7/05

BN0525051