


SEE MORE **BLUE**

See more **BLUE** in your lab
with great savings from
FISHER SCIENTIFIC!

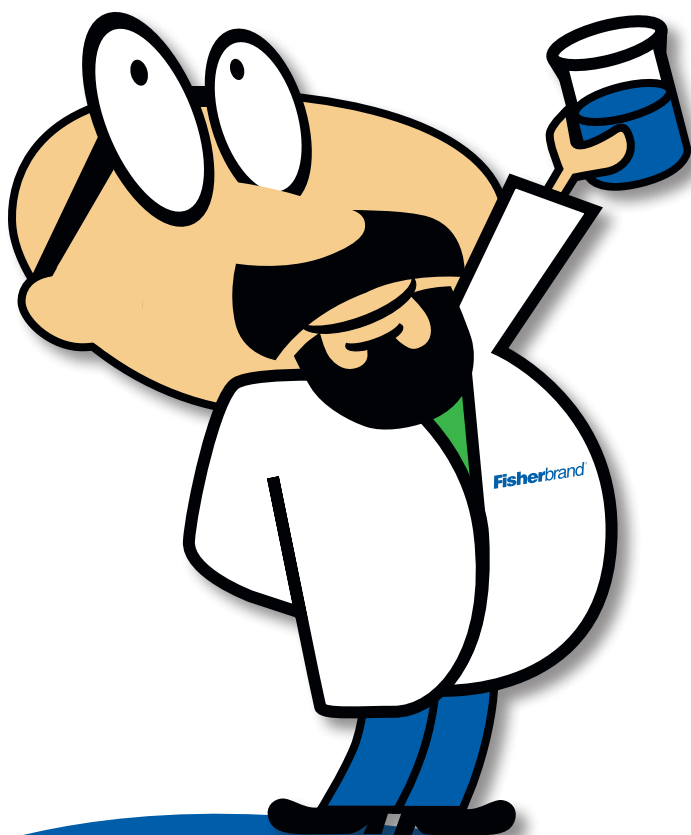

Glassware

Poxygrid Racks

Centrifuge Tubes

Wash Bottles

Mixers

Cryogenic Storage Vials

Tube Rotator

Cell Strainers

Microcentrifuge Tubes

SPECIAL OFFER 1

Purchase Three Cases of Fisherbrand Glassware, Receive a FREE Dr. Seymour Blue Lab Coat



Receive a FREE Dr. Seymour Blue Lab Coat

See Page 8 for details on how to redeem your FREE Dr. Seymour Blue Lab Coat. Please specify your size.

Fisherbrand Glassware – All products meet ASTM* specifications

Beakers

- Easy-to-read white graduated scale with marking area



Erlenmeyer Flasks

- Capacity scale measures approximate volume



Volumetric Flasks

- Class A, Calibrated "To Contain"



Cat. No.	Capacity	Units/Case
Low-Form Griffin Beakers		
FB-100-50	50mL	48
FB-100-100	100mL	48
FB-100-150	150mL	48
FB-100-250	250mL	48
FB-100-400	400mL	48
FB-100-600	600mL	36
FB-100-1000	1000mL	24
Heavy-Duty Low-Form Beakers		
FB-101-250	250mL	48
FB-101-400	400mL	48
FB-101-600	600mL	36
FB-101-1000	1000mL	24
FB-101-2000	2000mL	8
FB-101-4000	4000mL	4
Berzelius Beakers		
FB-102-100	100mL	48
FB-102-200	200mL	48
FB-102-300	300mL	48
FB-102-400	400mL	36
FB-102-600	600mL	24
FB-102-1000	1000mL	18

Cat. No.	Capacity	Units/Case
Narrow-Mouth Erlenmeyer Flasks		
FB-500-25	25mL	48
FB-500-50	50mL	48
FB-500-125	125mL	48
FB-500-250	250mL	48
FB-500-500	500mL	36
FB-500-1000	1000mL	24
FB-500-2000	2000mL	8
FB-500-4000	4000mL	1
FB-500-6000	6000mL	1
Wide-Mouth Erlenmeyer Flasks		
FB-501-125	125mL	48
FB-501-250	250mL	48
FB-501-500	500mL	36
FB-501-1000	1000mL	24
FB-501-2000	2000mL	8

Cat. No.	Capacity	Units/Case
Ground Glass Stopper Volumetric Flasks		
FB-400-10	10mL	12
10-205A	25mL	12
10-205B	50mL	12
10-205C	100mL	12
FB-400-200	200mL	12
10-205D	250mL	12
10-205E	500mL	12
10-205F	1000mL	4
FB-400-2000	2000mL	4
Snap Cap Volumetric Flasks		
FB-401-10	10mL	12
10-200A	25mL	12
10-200B	50mL	12
10-200C	100mL	12
10-200D	200mL	12
10-200E	250mL	12
10-200F	500mL	12
10-200G	1000mL	4
FB-401-2000	2000mL	4

SPECIAL OFFER 2

Purchase \$100 of Fisherbrand Poxygrid Racks, Receive a FREE Fisherbrand Wash Bottles Variety Pack

Choose your FREE Fisherbrand Wash Bottle Variety Pack

- 500mL capacity
- Pack of 6

Cat. No.


03-409-23H

See Page 8 for details on how to redeem your FREE Fisherbrand products.




Fisherbrand Poxygrid Racks

- Autoclavable
- Made of blue epoxy-coated steel wire
- Centrifuge tube racks hold 50mL tubes

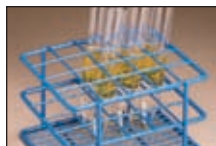

Cat. No.	Description
Test Tube Racks	
14-793-14	13mm, 72 Places
14-793-15	13mm, 108
14-793-11	16mm, 48
14-793-12	16mm, 72
14-793-13	16mm, 108
14-793-9	20mm, 40
14-793-10	20mm, 80
14-793-7	22mm, 40
14-793-8	22mm, 80
14-793-5	25mm, 80
14-793-6	25mm, 40
14-793-3	30mm, 24
14-793-4	30mm, 48
14-793-1	40mm, 24
14-793-2	40mm, 48

Cat. No.	Description
Test Tube Half Racks	
14-792-10	13mm, 36 Places
14-792-11	16mm, 24
14-792-12	20mm, 20
Centrifuge Tube Racks	
14-791-6A	8 Places
14-791-6B	16
14-791-6C	32

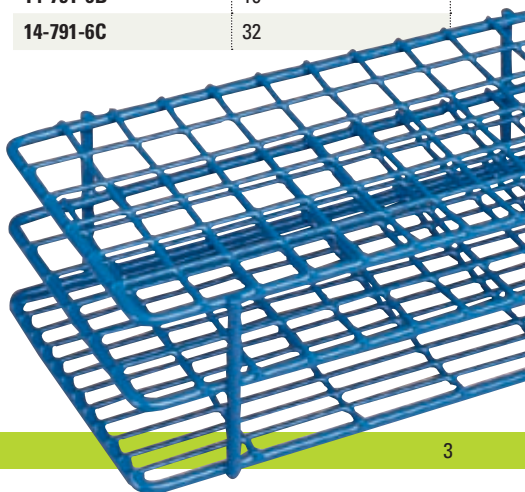

SPECIAL OFFER 3

Purchase Two Cases of Fisherbrand 50mL Centrifuge Tubes, Receive a FREE Case of Fisherbrand Cell Strainers



Choose your FREE Case of Fisherbrand Cell Strainers

- For use with all 50mL conical tubes
- Produce more uniform single-cell suspensions
- Case of 50

Cat. No.	Description
22-363-547	40µm, Blue
22-363-548	70µm, White
22-363-549	100µm, Yellow

See Page 8 for details on how to redeem your FREE Fisherbrand products.

Fisherbrand 50mL Centrifuge Tubes

- Conical bottoms
- 28 x 115mm O.D.
- Case of 500

Cat. No.	Description	Max Force (rcf)	Packaging
Centrifuge Tube, 50mL			
05-539-6	Plug Seal	6000 x g	Rack
05-539-7	Plug Seal	6000 x g	Rack
05-539-8	Flat Top	6000 x g	Rack
05-539-13	Flat Top	6000 x g	Sleeve
06-443-20	Plug Seal	9400 x g	Rack
06-443-21	Plug Seal	9400 x g	Sleeve
06-443-18	Flat Top	9400 x g	Rack
06-443-19	Flat Top	9400 x g	Sleeve



SPECIAL OFFER 4

Purchase a Fisher Scientific® Vortex Mixer, Receive a FREE Case of Fisherbrand Centrifuge Tubes



Fisherbrand®

Choose your **FREE** Case of Fisherbrand Centrifuge Tubes

- Polypropylene
- Max. force (rcf) 6000 x g

Cat. No.	Description	Capacity	Packaging
05-539-5	Plug Seal	15mL	Rack
05-539-12	Flat Top	15mL	Rack
05-539-6	Plug Seal	50mL	Rack
05-539-7	Plug Seal	50mL	Sleeve
05-539-8	Flat Top	50mL	Sleeve
05-539-13	Flat Top	50mL	Sleeve

See Page 8 for details on how to redeem your FREE Fisherbrand products.

Fisher Scientific Vortex Mixer

Fixed-Speed Mixer

- One-touch unit for high-speed mixing

Analog Mixer

- Variable analog speed control from 100 to 3200rpm for gentle to vigorous action

Digital Mixer

- Microprocessor control maintains set speed for consistent mixing

Pulsing Mixer

- Pulse feature reduces heat generation while delivering more effective mixing



Cat. No.	Description
Vortex Mixers (all 120V 50/60Hz)	
02-215-360	Fixed-speed Mixer, 3200rpm
02-215-365	Variable-speed Analog-control Mixer, 3200rpm
02-215-370	Variable-speed Digital-control Mixer, 3000rpm
02-215-375	Variable-speed Digital-control Mixer with Pulsing Action, 3000rpm

SPECIAL OFFER 5

Purchase Three Cases of Fisherbrand Cryogenic Storage Vials, Receive a Case FREE

Receive a FREE Case of Fisherbrand Cryogenic Storage Vials

See Page 8 for details on how to redeem your FREE Fisherbrand Products.

Limits: One redemption per lab, limit five free cases.



Fisherbrand Cryogenic Storage Vials

- Freestanding
- Sterile; not autoclavable
- Use with Fisherbrand Color Coders for easier sample identification

Cat. No.	Description	Bottom Style
Cryogenic Vials (1000 Units/Case)		
10-500-25	Externally Threaded, 1.2mL	Conical
10-500-26	Externally Threaded, 2mL	Conical
10-500-27	Externally Threaded, 5mL	Conical
12-567-500	Internally Threaded, 1.2mL	Conical, Star Foot
12-567-501	Internally Threaded, 2mL	Round, Star Foot
12-567-502	Internally Threaded, 5mL	Round, Star Foot

SPECIAL OFFER 6

Purchase a Fisher Scientific Tube Rotator AND 46-Place Tube Carousel, Receive a FREE Case of Fisherbrand Premium Microcentrifuge Tubes

Fisherbrand®

Choose your **FREE** Case of 1.5mL Fisherbrand Premium Microcentrifuge Tubes



- Made of high quality polypropylene
- Withstand forces of 30,000 x g
- Case of 5000

Cat. No.	Color
05-408-129	Natural
05-408-130	Red
05-408-131	Yellow
05-408-132	Blue
05-408-133	Green
05-408-134	Amber
05-408-135	Orange
05-408-136	Lavender
05-408-137	Assorted

See Page 8 for details on how to redeem your FREE Fisherbrand products.

Fisher Scientific Tube Rotator and 46-Place Tube Carousel

- Digital microprocessor control
- Variable speed of 4 to 80rpm
- 120V 50/60Hz



Cat. No.	Description
05-450-200	Tube Rotator

AND

Cat. No.	Description
05-450-202	46-Place Tube Carousel for 1.5/2.0mL Tubes

Product Redemption Form

SEE MORE BLUE in your lab with great savings from Fisher Scientific!

Choose from any of our special offers and redeem your free products below.

Please follow these instructions when requesting free products:

1. Place your orders with Fisher Scientific for the special offer products featured by calling **1-800-766-7000** or on **www.fishersci.com**.
2. To redeem the FREE product offers, complete this form and attach your Fisher Scientific proof of purchase for each offer—purchase order(s), packing slip(s), or invoice(s). They must accompany this form.
3. Fax completed form and proof of purchase(s) to Fisher Scientific at **412-249-5010**.
4. Each offer may be redeemed only once.

Please check the appropriate box below to indicate which Special Offers you are redeeming.

- Special Offer 1** Lab Coat Size S M L XL
- Special Offer 2** Part Number _____
- Special Offer 3** Part Number _____
- Special Offer 4** Part Number _____
- Special Offer 5** Part Number _____
- Special Offer 6** Part Number _____

Terms and Conditions: Offers valid on purchases made on April 1, 2009 through October 31, 2009 while supplies last. Fisher Scientific will honor any redemptions via fax before 11:59 PM, November 30, 2009. Purchases must be on a single order for each special offer, unless otherwise indicated. Limit of one special offer per customer unless otherwise indicated. All requested information on the redemption form must be completed to be a valid entry. Offers subject to change without notice; void where prohibited by law or company policy. Please allow six to eight weeks for delivery. Fisher Scientific and participating suppliers' employees, their parent, affiliates, subsidiaries, distributors, retailers, advertisers and advertising and promotional agencies and members of the immediate families of each are not eligible for promotional offers contained in this literature. Redemption of offers from the Fisher Scientific See More Blue brochure indicates permission to send notices of new products, prices and services, including advertisements for participating products.

Name: _____

Institution: _____ 9-digit Account Number: _____

Ship-to Address: _____

Room: _____ Bldg.: _____ Dept.: _____

City: _____ State: _____ Zip: _____

Phone: _____ Fax: _____

Email Address: _____

Fisher Scientific Sales Representative Name: _____

- Please check this box to be added to our mail/email list and to be made aware of other special offers.



Fisher Scientific

For customer service: call 1-800-766-7000
To fax an order: use 1-800-926-1166
To order online: www.fishersci.com

©2009 Thermo Fisher Scientific Inc. All rights reserved.
Litho in U.S.A. JJ/BM 3/09 09_1918

BN0304091